

Pan head drilling screw with collar and H recessed head pias®

Black galvanized steel (A2S), with Phillips head.

Drilling, threading, screwing-in – all in one work step


Therefore considerably reduced time and effort

Exact drilling diameter for each screw connection

- Resulting in minimisation of thread tolerance
- Always an optimum connection

Prevents installation errors

Material	Steel
Surface	Zinc plated black
Internal drive	H2

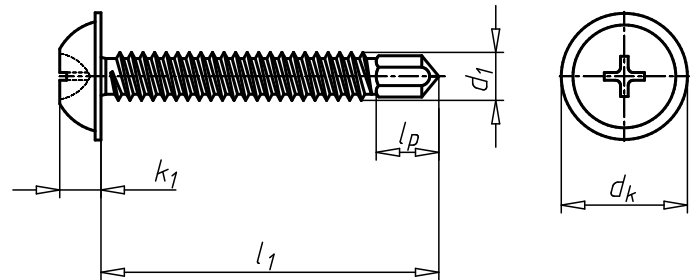


Nominal diameter (d ₁)	Length (l ₁)	Head diameter (d _k)	Head height (k ₁)	Drill tip length (l _p)	Art. no.	P. Qty.
4.2 mm	13 mm	11 mm	2.6 mm	3.7 mm	0218 24 13	250/1000
4.2 mm	16 mm	11 mm	2.6 mm	3.7 mm	0218 24 16	250/1000
4.2 mm	19 mm	11 mm	2.6 mm	3.7 mm	0218 24 19	250/1000
4.2 mm	25 mm	11 mm	2.6 mm	3.7 mm	0218 24 25	250/500
4.8 mm	16 mm	12.75 mm	3.3 mm	4.5 mm	0218 25 16	250/1000
4.8 mm	22 mm	12.75 mm	3.3 mm	4.5 mm	0218 25 22	250/1000
4.8 mm	35 mm	12.75 mm	3.6 mm	4.5 mm	0218 25 35	500

Can be stored in ORSY® system

Details/Application

The self-drilling screw for fastening plastic and thin sheet metal to metal sub-structures.

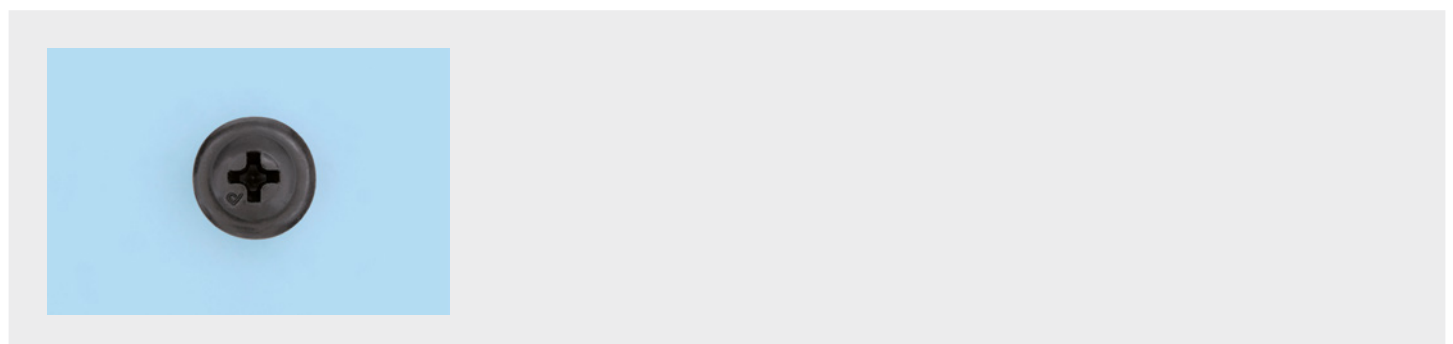

Notice

The pressed-on flange generates a lower surface pressure, which helps to prevent stress cracks
Contact pressure during use approx. 100 N/screw in with depth stop if necessary

Galvanized drilling screws may only be used where dampness is not to be expected.
For fasteners with a construction permit, the permit, and in particular Part 2 „Special regulations“, must always be observed.