


Washer for cheese-head screw

DIN 433 stainless steel, A4, 140 HV

Standards	DIN 433
Material	Stainless steel A4
Vickers hardness, HV	140 HV
Surface	Plain
RoHS-compliant	Yes

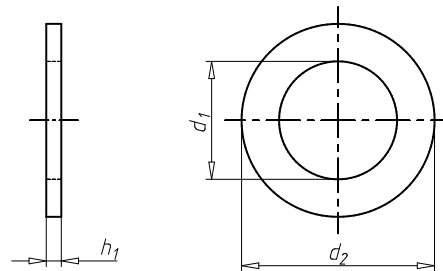

Suitable for screw thread	Internal diameter (d_1)	Outer diameter (d_2)	Thickness (h_1)	Art. no.	P. Qty.
M2.5	2.7 mm	5 mm	0.5 mm	0412 907 25	2000 /10000
M3	3.2 mm	6 mm	0.5 mm	0412 907 3	5000
M3.5	3.7 mm	7 mm	0.5 mm	0412 907 35	1000
M4	4.3 mm	8 mm	0.5 mm	0412 907 4	5000
M5	5.3 mm	9 mm	1 mm	0412 907 5	2000
M8	8.4 mm	15 mm	1.6 mm	0412 907 8	500
M10	10.5 mm	18 mm	1.6 mm	0412 907 10	500
M12	13 mm	20 mm	2 mm	0412 907 12	1000
M14	15 mm	24 mm	2.5 mm	0412 907 14	200
M16	17 mm	28 mm	2.5 mm	0412 907 16	200
M18	19 mm	30 mm	2.5 mm	0412 907 18	100
M20	21 mm	34 mm	3 mm	0412 907 20	100
M24	25 mm	39 mm	4 mm	0412 907 24	1

Can be stored in ORSY® system

Details/Application

Preferably for cheese-head screws