


Lock washer, inch

DIN 127, spring steel, mechanically applied zinc coating

Material	Spring steel
Surface	Zinc plated

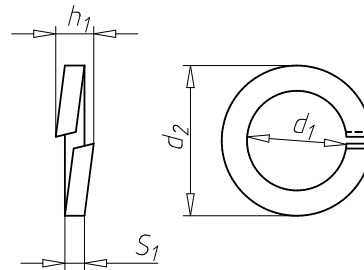

Internal diameter (d ₁)	Outer diameter (d ₂)	Thickness (s ₁)	Height (h ₁)	Art. no.	P. Qty.
1/2 in	22.07 mm	3.18 mm	4.34 mm	0442 12	100
1/4 in	12.37 mm	1.57 mm	2.77 mm	0442 14	100
3/4 in	32.13 mm	4.78 mm	5.94 mm	0442 34	100
3/8 in	17.27 mm	2.38 mm	3.58 mm	0442 38	100/500 /1000
5/8 in	27.25 mm	3.96 mm	5.18 mm	0442 58	100
5/16 in	14.81 mm	1.98 mm	3.18 mm	0442 516	100/500
7/16 in	19.71 mm	2.77 mm	3.96 mm	0442 716	100/1000