

Wire stripping pliers, adjustable

Integrated cutting depth adjustment for fine adjustment with different insulation materials

- Adjustable longitudinal stop: 3-18 mm
- Integrated cable cutters: Flexible up to 10.0 mm², rigid up to 1.5 mm²
- Replaceable knife block and longitudinal stop
- Ergonomically shaped 2-component handle for comfortable and effortless work
- Made in Sweden

Length x width x height	191 x 20 x 90 mm
Material	Plastic/metal
Material of the grip handle	2-component plastic




Illustration only



Blade geometry	Min./max. wire cross section	Min./max. American Wire Gauge (AWG) (AWG)	Art. no.	P. Qty.
O-shaped	4-16 mm ²	12-5	0714 108 116	1
Straight	0.02-10 mm ²	34-8	0714 108 10	1

Details/Application

PVC-insulated single cores, e.g. H05V-K, H07V-K, H05V-U, H07V-U

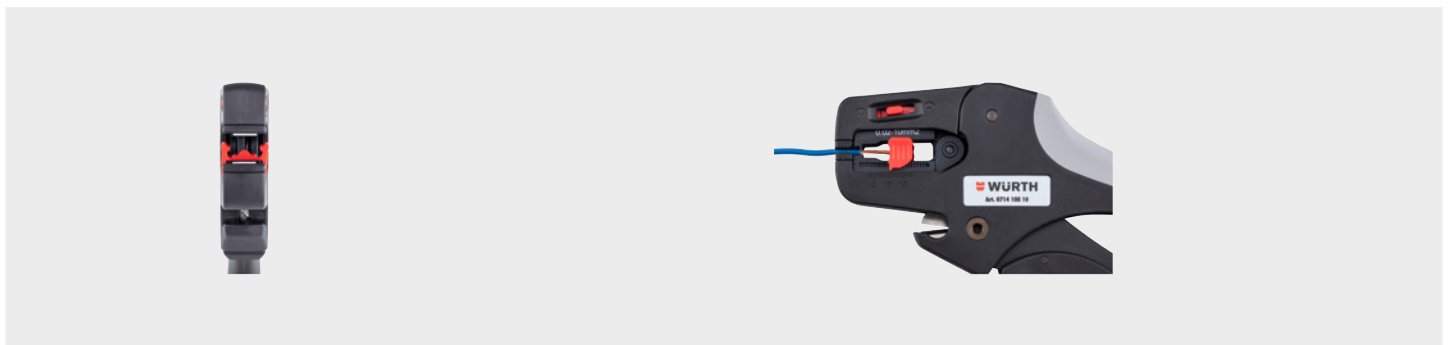

Notice

Not suitable for working on or in the vicinity of live parts.

Related products for	Designation	Art. no.
0714 108 10	Cartridge 0.02-10 mm ²	0714 108 101
	Cartridge 0.1-4 mm ² PTFE-Kabel	0714 108 102
	Retaining jaws	0714 108 105
	Cartridge 4-16 mm ²	0714 108 16
0714 108 116	Cartridge 0.02-10 mm ²	0714 108 101
	Cartridge 0.1-4 mm ² PTFE-Kabel	0714 108 102
	Retaining jaws	0714 108 105
	Cartridge 4-16 mm ²	0714 108 16