


T-handle socket wrench

For hexagon head screws

- Blade: Round blade, chrome-plated
- Tip: DIN 475/2
- Inner bore for protruding threaded shafts
- Standard: DIN 3125

Material of grip handle	2-component plastic
Surface	Nickel plated

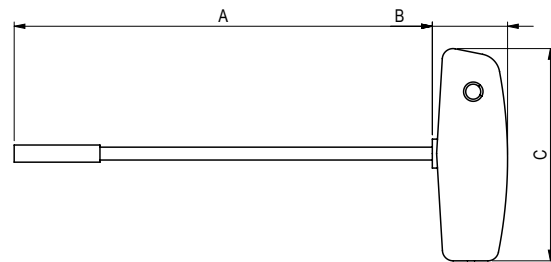

Width across flats	Blade length (A)	Handle width x handle length (BxC)	Art. no.	P. Qty.
6 mm	125 mm	35 x 104 mm	0613 120 06	1/10
6 mm	200 mm	35 x 104 mm	0613 121 06	1/10
7 mm	125 mm	35 x 104 mm	0613 120 07	1/10
7 mm	200 mm	35 x 104 mm	0613 121 07	1/10
8 mm	125 mm	35 x 104 mm	0613 120 08	1/10
8 mm	200 mm	35 x 104 mm	0613 121 08	1/10
8 mm	300 mm	35 x 104 mm	0613 122 08	1/10
9 mm	125 mm	35 x 104 mm	0613 120 09	1/10
9 mm	200 mm	35 x 104 mm	0613 121 09	1/10
10 mm	125 mm	35 x 104 mm	0613 120 10	1/10
10 mm	230 mm	35 x 104 mm	0613 121 10	1/10
10 mm	300 mm	35 x 104 mm	0613 122 10	1/10
11 mm	125 mm	35 x 104 mm	0613 120 11	1/10
11 mm	230 mm	35 x 104 mm	0613 121 11	1/10
11 mm	300 mm	35 x 104 mm	0613 122 11	1/10
12 mm	125 mm	35 x 104 mm	0613 120 12	1/10
12 mm	230 mm	35 x 104 mm	0613 121 12	1/10
12 mm	300 mm	35 x 104 mm	0613 122 12	1/10
13 mm	125 mm	35 x 104 mm	0613 120 13	1/10
13 mm	230 mm	35 x 104 mm	0613 121 13	1/10
13 mm	300 mm	35 x 104 mm	0613 122 13	1/10
14 mm	125 mm	35 x 104 mm	0613 120 14	1/10

Width across flats	Blade length (A)	Handle width x handle length (BxC)	Art. no.	P. Qty.
14 mm	300 mm	35 x 104 mm	0613 122 14	1/10
15 mm	125 mm	35 x 104 mm	0613 120 15	1/10
16 mm	125 mm	35 x 104 mm	0613 120 16	1/10
17 mm	125 mm	39 x 117 mm	0613 120 17	1/10

Details/Application

