




Digital vernier calipers

With data output RS 232


- Stainless steel, hardened
- Features: mm/inch switch, on/off, zero (0-button)
- Degree of protection IP54
- Measuring surfaces ground and lapped
- Flat depth gauge
- Top locking screw
- Battery included



Illustration only

	Max. length measuring range	Length of jaw	Art. no.	P. Qty.
	150 mm	40 mm	0715 76 122	1
	200 mm	50 mm	0715 76 124	1
	300 mm	60 mm	0715 76 126	1

Details/Application

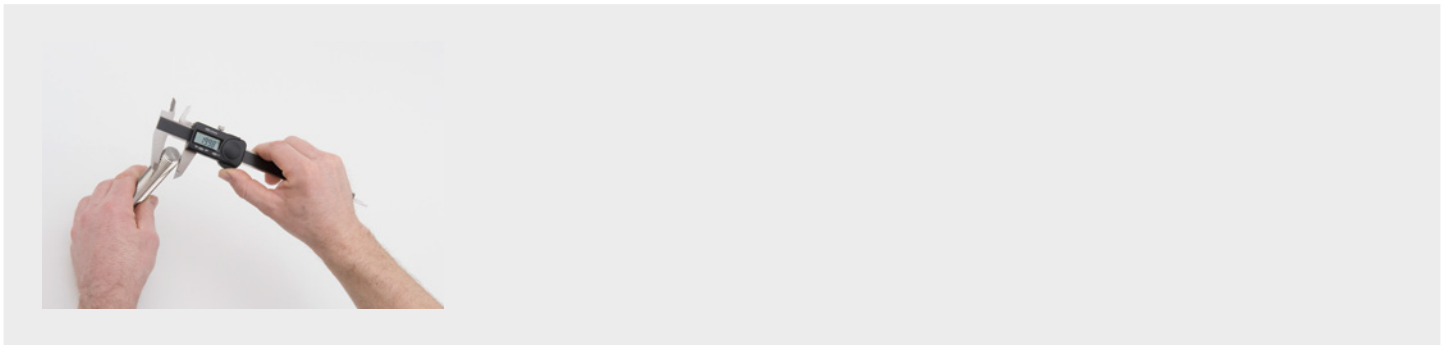

Notice

Supplied in plastic box