


Single wire seal (SEAL)

For non-insulated cable connectors

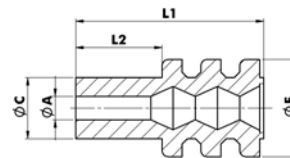

Seal diameter (C)	Min./max. diameter of insulation (A)	Suitable for hole diameter	Collar diameter (F)	Length	Colour	Art. no.	P. Qty.
2.6 mm	1.2-2.1 mm	3.6 mm	3.9 mm	7.6 mm	Grey	0558 991 403	100
2.9 mm	1.7-2.1 mm	4 mm	4.5 mm	7 mm	Red	0558 991 404	100
2.9 mm	1.9-2.5 mm	4 mm	4.5 mm	7 mm	Yellow	0558 991 405	100
3.4 mm	1.2-2.1 mm	5.15 mm	5.65 mm	7.5 mm	Orange	0558 991 406	100
3.4 mm	1.4-2.1 mm	5.4 mm	6 mm	7.5 mm	Pure white	0558 991 408	100
3.4 mm	1.7-2.4 mm	5.15 mm	6.1 mm	7.8 mm	Yellow	0558 991 41	100
3.4 mm	1.9-3 mm	5.15 mm	5.65 mm	7.5 mm	Red brown	0558 991 407	100
3.4 mm	2.2-3 mm	5.4 mm	6 mm	7.5 mm	Orange	0558 991 409	100
3.4 mm	2.5-3.3 mm	5.15 mm	6.1 mm	7.8 mm	Red	0558 991 42	100
4.25 mm	1.2-2.1 mm	6.7 mm	7.25 mm	7.5 mm	Red brown	0558 991 410	100
4.25 mm	1.9-3 mm	6.7 mm	7.25 mm	7.5 mm	Grey	0558 991 411	100
6 mm	1.2-2.1 mm	8.2 mm	9 mm	7.5 mm	Colza Yellow	0558 991 412	100
6 mm	1.9-3 mm	8.2 mm	9 mm	7.5 mm	Pure white	0558 991 413	100
6 mm	2.7-3.7 mm	8.2 mm	9 mm	7.5 mm	Red brown	0558 991 414	100
6 mm	3.4-4.4 mm	8.2 mm	9 mm	7.5 mm	Pale green	0558 991 415	100

Compatible with ORSY® storage system

Details/Application

