

## Cordless drill driver ABS 18 POWER M-CUBE

**Very powerful, handy cordless drill screwdriver designed specifically for tough construction site conditions with a torque of 140 Nm. Developed by Würth to meet the requirements of craftsmen**

### Robust design

For demanding use on construction sites, all components will also survive a fall from normal working heights.

### Continuous monitoring of the motor

The electronic motor protection function switches the motor off ahead of time in the event of blockage, overloading or overheating.

### Long motor service life

Efficient, low-maintenance, brushless EC motor with power reserves. Also maintains a more stable speed curve under load.

### Maximum service life and low wear

- 13 mm Röhmetal chuck with soldered carbide clamping jaws
- Electronic signal switch

### Well-lit working area

LED lamp on the battery block

### 2 Years WÜRTH MASTERPLUS Warranty for wear damage

The current WÜRTH MASTERPLUS warranty conditions must be observed.

### 3 Years Warranty on manufacturing and material defects

Excluded are damages caused by improper use, overloading or failure to observe the operating instructions.




Illustration only



Nominal voltage	18 V/DC
Idle speed 1st/2nd gear min./max.	0-550/0-2000 rpm
Max. torque hard/soft	140/60 Nm
Min./max. drill chuck span width	1.5-13 mm
Drill chuck holder	1/2 inch x 20 UNF
Max. drilling diameter in steel	13 mm
Max. drilling diameter in aluminium	13 mm
Max. recommended drilling diameter in metal	13 mm
Max. screw diameter	12 mm
Length	205 mm

Height	260 mm
Weight of machine with rechargeable battery	2.2 kg

 
Included in delivery	Number of rechargeable batteries/batteries	Rechargeable battery/battery capacity	Art. no.	P. Qty.
Batteries not included, additional accessories not included	0 PCS	0 Ah	<b>5701 404 000</b>	1
With 2 x 4 Ah batteries, additional accessories not included	2 PCS	4 Ah	<b>5701 404 008</b>	1



## Details/Application




Electronic motor protection function:

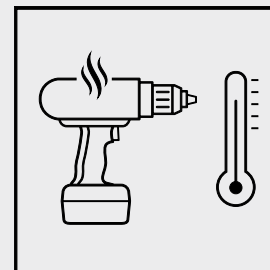


Continuous motor monitoring increases its service life, since the motor is shut off quickly in the event of overloading, overheating or a jam.

20-stage adjustment:

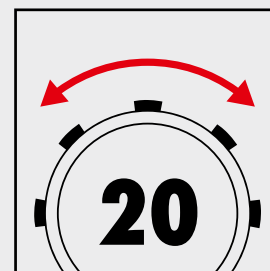


Precise and effective working through ideal torque setting and optimum throughput.

Brushless motor:

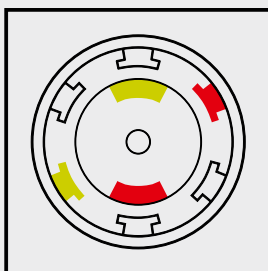

Longer working life of the EC-motors, low-maintenance, as carbon brushes do not have to be changed. More efficient and powerful motor in a smaller size.

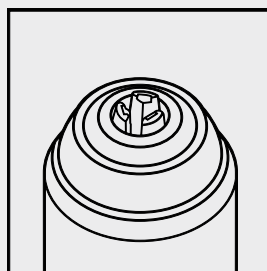

Drill chuck:  
13 mm solid metal drill chuck with carbide jaws for optimal retention of the clamped tool.

**Contents for art. no. 5701 404 008**

<b>Designation</b>	<b>Art. no.</b>	<b>Quantity</b>
System case 8.4.2	<b>5581 011 000</b>	1
Battery Li-ion 18 V BASIC M-CUBE 4 Ah	<b>5704 180 000</b>	2
Charger ALG 18 V M-CUBE ALG 18/6 FAST	<b>5705 860 000</b>	1
Case insert for MASTER machines	<b>5801 842 404</b>	1

**Related products**

	<b>Art. no.</b>
Twist drill HSCo DIN 338 MFD Speed	<b>0626 930 800</b>
Forstner drill bit Longlife & speed	<b>0650 990 350</b>
Machine tap HSCo Multi Performance blind hole DIN 371/376	<b>0658 800 600</b>
Safety goggles Cetus®X-treme	<b>0899 102 380</b>