


## Pneumatic impact screwdriver DSS 1 inch L

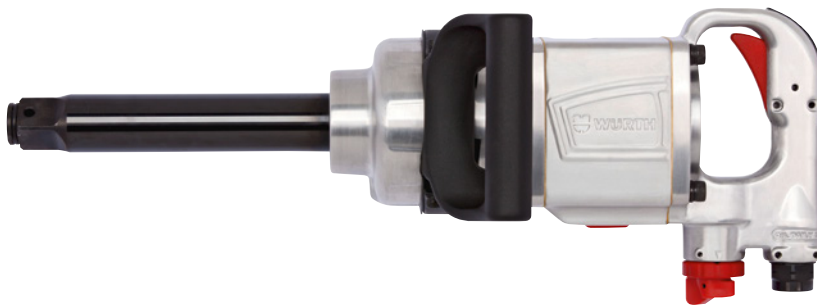

**Highly robust, powerful impact screwdriver with long square drive.**

### Very durable

Robust aluminium housing

### Very handy and user-friendly

Ergonomically designed handle, additional handle rotates 360°, user-friendly right/left changeover and adjustable trigger.

**Low air consumption, despite maximum performance values and long service life**

High-quality double hammer impact mechanism

**2 Years WÜRTH MASTERPLUS Warranty for wear damage**

The current WÜRTH MASTERPLUS warranty conditions must be observed.

**3 Years Warranty on manufacturing and material defects**

Excluded are damages caused by improper use, overloading or failure to observe the operating instructions.

**Art. no. 0703 780 0**


P. Qty.: 1

Individually boxed

Type description	DSS 1 inch L
Tool holding device	1-inch external square
Max. working torque	1870 Nm
Max. releasing torque	2440 Nm
Sound-pressure level	95 dB
Vibration	9.26 m/s <sup>2</sup>
Working pressure	6.3 bar
Weight of machine	10.93 kg
Min. hose inner diameter	11 mm
Air consumption	370 l/min
Connection thread	1/2 inch
Length x width x height	512 x 109 x 188 mm

Level	Tightening torques Nm (approx. values)	Releasing torque Nm
1	996	Max. 2,440
2	1,355	
3	1,518	
4	1,870	

## Details/Application

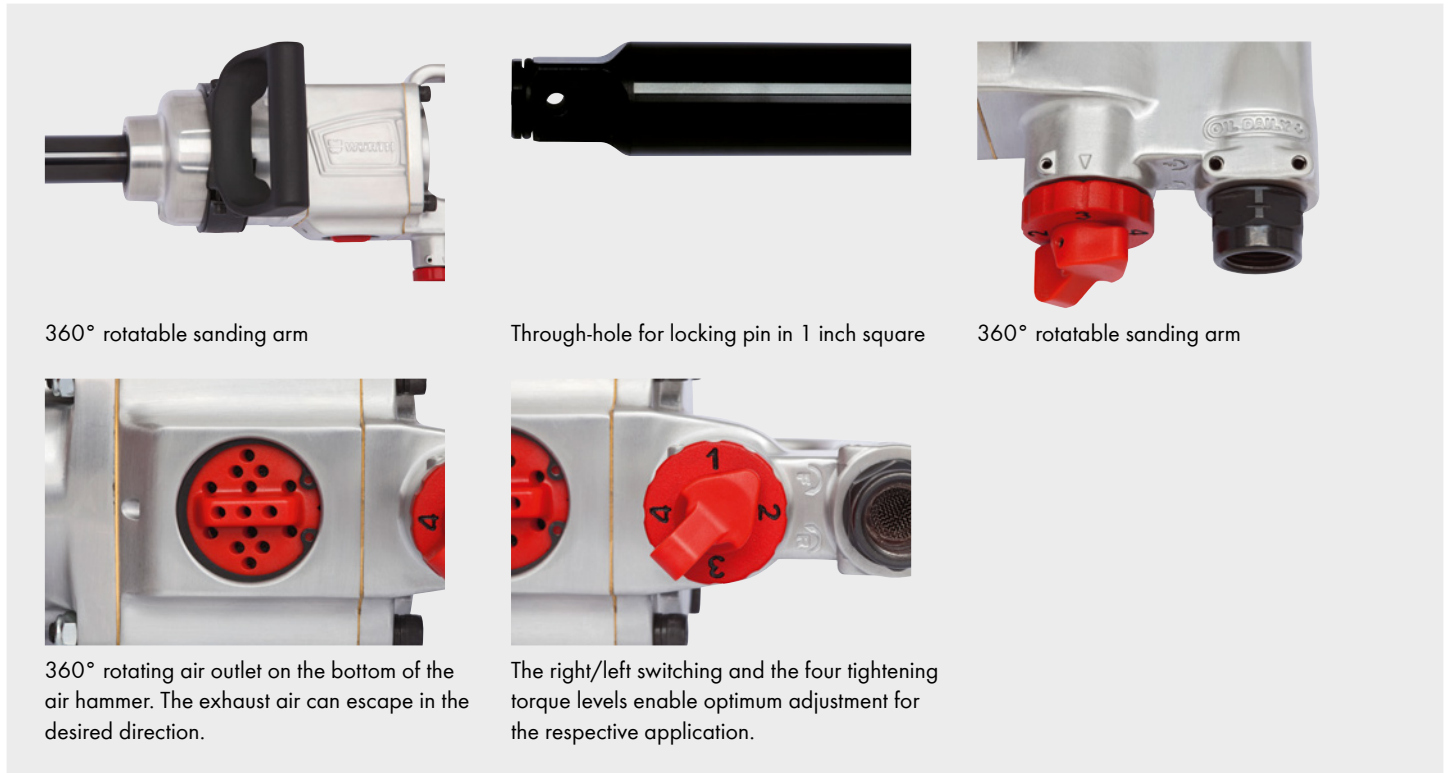

## Notice

- Impact screwdrivers are not torque screwdrivers. Connections requiring a specific torque must be checked by means of a torque measuring device after tightening with the impact screwdriver.
- The operating torque is the torque usually achieved under average working conditions. It is dependent on the highly varying ambient conditions (air pressure, hose diameter, soiling etc.).
- When used regularly, the machine should be lightly oiled via the pneumatic air supply every day. The use of a mist lubricator is recommended

Plug-in nipple not included in scope of delivery

Related products	Art. no.
Plug-in nipple S2000 MT	<b>0699 100 612</b>
1-inch impact socket wrench insert 24 mm	<b>0714 15 01</b>
1-inch impact socket wrench insert 27 mm	<b>0714 15 02</b>
1-inch impact socket wrench insert 30 mm	<b>0714 15 03</b>
1-inch impact socket wrench insert 32 mm	<b>0714 15 04</b>
1-inch impact socket wrench insert 34 mm	<b>0714 15 041</b>
1-inch impact socket wrench insert 36 mm	<b>0714 15 05</b>
1-inch impact socket wrench insert 33 mm	<b>0714 15 33</b>
1-inch impact socket wrench insert 38 mm	<b>0714 15 38</b>
1-inch impact socket wrench insert 41 mm	<b>0714 15 41</b>
1-inch impact socket wrench insert 42 mm	<b>0714 15 42</b>
1-inch impact socket wrench insert 46 mm	<b>0714 15 46</b>
1-inch impact socket wrench insert 50 mm	<b>0714 15 50</b>
1-inch impact socket wrench insert 55 mm	<b>0714 15 55</b>
1-inch impact socket wrench insert 60 mm	<b>0714 15 60</b>
1-inch impact socket wrench insert 65 mm	<b>0714 15 65</b>
1-inch impact socket wrench insert 70 mm	<b>0714 15 70</b>

<b>Related products</b>	<b>Art. no.</b>
Special oil 1 l	<b>0893 050 5</b>