

Cordless LED work lamp Sound

Small and compact work lamp with built-in speaker

COB-LED technology

For a powerful luminous efficacy with absolutely even illumination

Lithium-ion battery technology

Short charging time; lamp can be used for long periods

Wireless function

Simply connect the devices wirelessly and control the music from your mobile phone.

Flexible holder

The flexible base with a strong magnet allows the beam angle to be optimally adapted to the respective working conditions.



Min./max. luminous flux	300/600 lm
Colour temperature	6000 K
Min./max. luminous period	2.5-5 h
Charging time	5 h
Impact resistance	IK07
IP protection type, lamp	IP 65
IP protection type charger	IP 20
Nominal voltage	3.7 V/DC
Rechargeable battery/ battery capacity	5200 mAh
Type of rechargeable battery/battery	Li-Ion
Protection class lamp	Protection class III/safety extra-low voltage
Protection class charger	Protection class II/protective insulation
Min./max. charging voltage	100-240 V/AC
Min./max. frequency	50/60 Hz
Power rating	7 W
Connection type	USB, mini DC
Power-lead length	1000 mm
Min./max. operating temperature	-10 to 40 °C
Charging temperature min./ max.	5 to 30 °C
Width x height x depth	87 x 92 x 75 mm
Plug type	C


Art. no. 0827 981 800

P. Qty.: 1

Scope of delivery: Lamp, USB/mini DC cable, power supply 100-240 V 50/60 Hz

Details/Application

For indoor and outdoor use

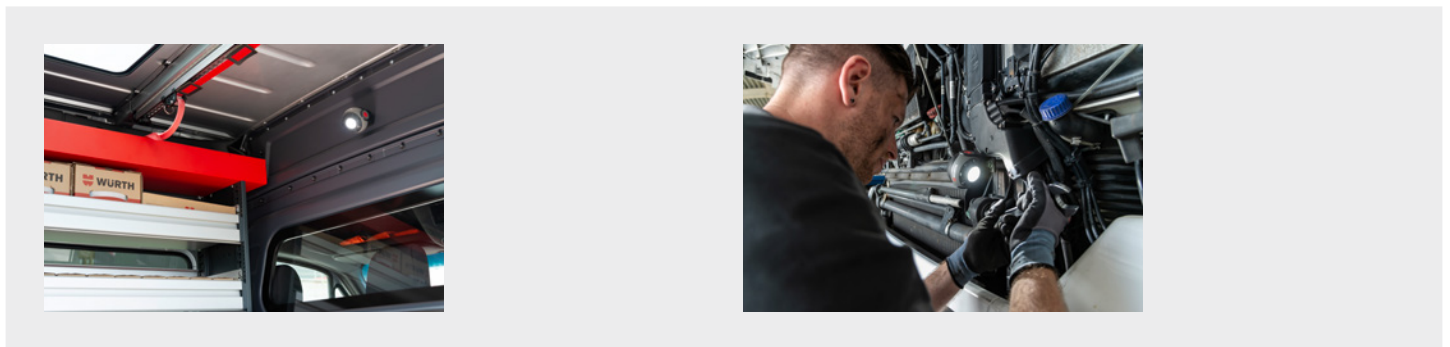

Spare parts	Art. no.
Charger	0827 981 801