

## Cordless sabre saw AFS 18 COMPACT M-CUBE

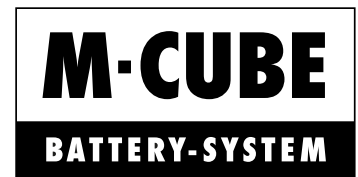


Illustration only

### Powerful and robust M-CUBE cordless sabre saw

- Built-in overload and over-temperature protection functions protect the machine from overload
- Long motor service life: Efficient, low-maintenance, brushless EC motor with power reserves
- Additional protection against chips by means of cover gratings over ventilation slots
- Safe working, as the machine can only be started up after first unlocking
- 3 stroke stages allow individual adjustment of the stroke rate to the respective material
- Soft grip ensures a comfortable, non-slip hold

### 2 Years WÜRTH MASTERPLUS Warranty for wear damage and replacement of batteries and chargers

The current WÜRTH MASTERPLUS warranty conditions must be observed.

### 3 Years Warranty on manufacturing and material defects

Excluded are damages caused by improper use, overloading or failure to observe the operating instructions.

Nominal voltage	18 V/DC
Min./max. idle stroke speed	0-3200 rpm
Stroke length	28 mm
Tool holding device	Quick-change holder
Weight of machine with rechargeable battery	3.6 kg
Weight of machine without rechargeable battery	2.9 kg
Length	443 mm
Width	80 mm
Height	200 mm
Max. cutting depth in wood	255 mm
Weight of outer packaging	0.3 kg

Number of rechargeable batteries/batteries	Art. no.	P. Qty.
0 PCS	<b>5701 412 000</b>	1
2 PCS	<b>5701 412 004</b>	1




5701 412 004 0001

Find out more about the topic of occupational health and safety premiums and find all Würth products that are supported by BG BAU at: [www.wuerth.de/bgbau](http://www.wuerth.de/bgbau)


## Details/Application

Brushless motor:

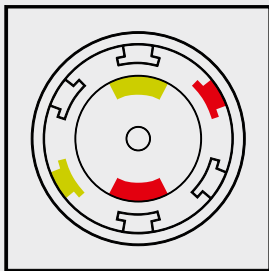


Longer working life of the EC-motors, low-maintenance, as carbon brushes do not have to be changed. More efficient and powerful motor in a smaller size.


Stroke control

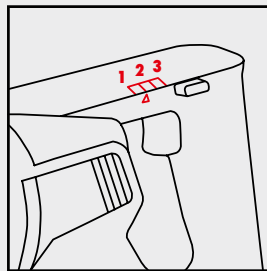


Release switch

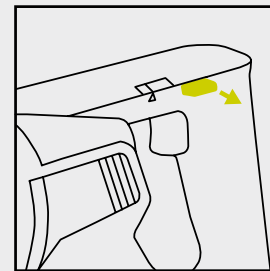

Electronic motor protection function

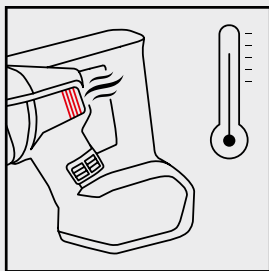

Deadman's switch

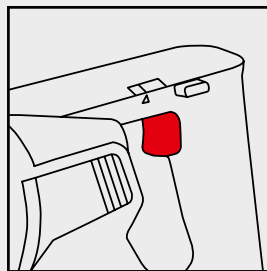

### Contents for art. no. 5701 412 004

Designation	Art. no.	Quantity
System case 8.4.2	<b>5581 011 000</b>	1
Battery Li-ion 18 V BASIC M-CUBE 5 Ah	<b>5703 450 000</b>	2
Charger ALG 18 V M-CUBE ALG 18/6 FAST	<b>5705 860 000</b>	1
Case insert for MASTER machines	<b>5801 842 412</b>	1

### Related products

	Art. no.
Sabre saw blade Rescue, four stars For rescue operations Length:150 mm; 3 PCS	<b>0615 515 030</b>
Sabre saw blade, construction, three stars Demolition, construction site professional Length:225 mm; 5 PCS	<b>0615 722 842</b>
Sabre saw blade, construction, three stars For brick/gas concrete Length:455 mm; 1 PCS	<b>0615 745 512</b>

<b>Related products</b>	<b>Art. no.</b>
Sabre saw blade, wood, three stars Multiblade jigsaw blade Length:200 mm; 5 PCS	<b>0615 820 340</b>
Sabre saw blade, metal, three stars Demolition Length:150 mm; 5 PCS	<b>0615 915 029</b>
Sabre saw blade, metal, three stars Multiblade jigsaw blade Length:150 mm; 5 PCS	<b>0615 915 030</b>
Sabre saw blade, metal, three stars Multiblade jigsaw blade Length:150 mm; 25 PCS	<b>0615 915 031</b>
Sabre saw blade, metal, three stars Multiblade jigsaw blade Length:150 mm; 30 PCS	<b>0615 915 032</b>
Sabre saw blade, metal, four stars Demolition Longlife/stainless steel professional Length:150 mm; 3 PCS	<b>0615 915 300</b>
Storage box 180 x 85 x 40 mm	<b>0615 000 000</b>
Storage box 300 x 100 x 45 mm	<b>0615 000 001</b>
Sabre saw blade, construction, three stars Demolition, construction site professional Length:225 mm; 5 PCS	<b>0615 722 842</b>
Sabre saw blade, construction, three stars For brick/gas concrete Length:455 mm; 1 PCS	<b>0615 745 512</b>
Sabre saw blade, wood, three stars Multiblade jigsaw blade Length:200 mm; 5 PCS	<b>0615 820 340</b>
Sabre saw blade, metal, three stars Demolition Length:228 mm; 5 PCS	<b>0615 922 829</b>
Safety goggles Cetus®X-treme	<b>0899 102 380</b>
Ear defenders WNA 200/F	<b>0899 300 430</b>
Protective glove MultiFit Nitrile	<b>0899 405 216</b>