

Pneumatic rod grinder DSW 22

Long-life, handy rod grinder, angled design, with tool-free speed control and rubberised handle to protect against vibrations and cold hands.

Keeps hands warm

Rubberised handle

Effortless work and low vibration

Lightweight, compact design

Connection hose does not tangle

Rotating compressed air connection

2 Years WÜRTH MASTERPLUS Warranty for wear damage

The current WÜRTH MASTERPLUS warranty conditions must be observed.

3 Years Warranty on manufacturing and material defects

Excluded are damages caused by improper use, overloading or failure to observe the operating instructions.



Design	Angled
Max. idle speed	22000 rpm
Power output	224 W
Max. drill chuck span width	6 mm
Min. hose inner diameter	8 mm
Weight of machine	0.5 kg
Air consumption	113 l/min
Connection thread	1/4 inch


Art. no. 0703 231 0

P. Qty.: 1

Individually boxed

Details/Application

Rod grinder developed specifically for the toughest applications (e.g. deburring work) with high power reserves.

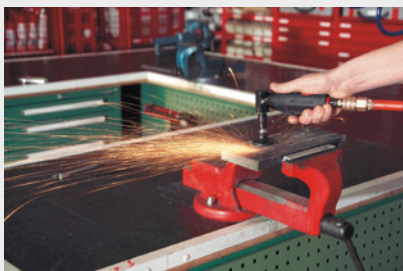

Notice

- When used regularly, the machine should be lightly oiled via the compressed air supply every day. The use of a mist oiler is recommended.
- Plug-in nipple not included in the scope of delivery

Contents for art. no. 0703 231 0		
Designation	Art. no.	Quantity
Open-ended wrench	0709 230 027	1

Related products	Art. no.
Holder Washer diameter 50 mm; Length 65 mm	0586 578 01
Holder Washer diameter 75 mm; Length 65 mm	0586 578 02
Speed rough grinding disc for steel	0664 160 606
Clamping mandrel for cutting discs and grinding discs Suitable for bore diameter 6 mm	0664 976
Clamping mandrel for cutting discs and grinding discs Suitable for bore diameter 10 mm	0664 978
Small Abrasives Mini Compact Fleece Disc	0673 215 040
Mini Nylon Fleece Disc 50 mm	0673 22 50
Mini Nylon Fleece Disc 75 mm	0673 22 75
Small mist lubricator	0699 070 314
Plug-in nipple S2000 MT	0699 100 614
Special oil 1 l	0893 050 5