

## Pneumatic multi-cutter DMS 2



**Powerful unit for removing bonded windscreens, for cutting work on vehicle bodies and sanding work in corners and around edges.**

**For use with standard blades and accessories**

Universal hex Mount

**Mechanical cutting without harmful smoke development**

Oscillating motion

**No accidental switch-on and continuously adjustable blade oscillation rate**

Exhaust air system with exhaust air hose

Deflects the exhaust air away from the user and work area

**For prolonged machine life**

High-quality ball bearings

**2 Years WÜRTH MASTERPLUS Warranty for wear damage**

The current WÜRTH MASTERPLUS warranty conditions must be observed.

**3 Years Warranty on manufacturing and material defects**

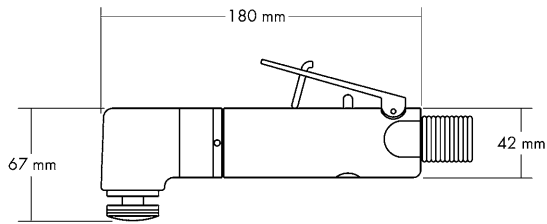
Excluded are damages caused by improper use, overloading or failure to observe the operating instructions.

Type description	DMS 2
Min./max. idle orbital rate	0-20000 1/min
Working pressure	6.3 bar
Air consumption	370 l/min
Min. hose inner diameter	8 mm
Tool holding device	Hexagon
Weight of machine	1.1 kg
Connection thread	1/4 inch
Width	42 mm
Height	67 mm

**Art. No. 0703 862 1**

P. Qty.: 1

**Supplied in a case**


**Contents for Art. No. 0703 862 1**

Designation	Art. No.	Quantity
Exhaust-air system	<b>0709 861 035</b>	1
Open-ended wrench	<b>0709 861 040</b>	1
Double-headed wrench	<b>0709 861 041</b>	1
Oiler/Mist lubricator	<b>0709 861 055</b>	1

Related products	Art. No.
Velcro dry sandpaper, round Grid size P40	<b>0572 326 004</b>
Velcro dry sandpaper, round Grid size P60	<b>0572 326 006</b>
Velcro dry sandpaper, round Grid size P80	<b>0572 326 008</b>
Velcro dry sandpaper, round Grid size P120	<b>0572 326 012</b>
Velcro dry sandpaper, round Grid size P180	<b>0572 326 018</b>
Velcro dry sandpaper, round Grid size P240	<b>0572 326 024</b>
Hook and loop dry sandpaper triangle Grid size P100	<b>0572 75 100</b>
Hook and loop dry sandpaper triangle Grid size P120	<b>0572 75 120</b>
Hook and loop dry sandpaper triangle Grid size P150	<b>0572 75 150</b>
Hook and loop dry sandpaper triangle Grid size P180	<b>0572 75 180</b>
Hook and loop dry sandpaper triangle Grid size P40	<b>0572 75 40</b>
Hook and loop dry sandpaper triangle Grid size P60	<b>0572 75 60</b>
Hook and loop dry sandpaper triangle Grid size P80	<b>0572 75 80</b>
Adapters A2	<b>0696 500 3</b>
Knife blade U-shaped	<b>0696 579</b>
HSS saw blade	<b>0696 631</b>
HSS saw blade	<b>0696 681</b>
Plug-in nipple S2000 MT	<b>0699 100 614</b>
Special oil 1 l	<b>0893 050 5</b>