

Angle grinder EWS 17-125-EQ POWER



Powerful 1,700-watt angle grinder with good handling, fast material removal and maximum productivity. Ideal for heavy-duty roughing and cutting work

Constant electronics

Rotation speed remains constant, even under load.

6-stage speed control

Allows the user to select the ideal speed for the application.

Restart protection

Prevents accidental start-up after a power interruption.

Recoil protection

Ensures no recoil if the disk locks thanks to mechanical decoupling.

Overload protection and soft-start

Considerably increases the service life of the machine.

Quick-adjustable protective hood and quick-clamping nut

- The hood allows tool-free adjustment.
- The nut allows tool-free disc change.

2 Years WÜRTH MASTERPLUS Warranty for wear damage

The current WÜRTH MASTERPLUS warranty conditions must be observed.

3 Years Warranty on manufacturing and material defects

Excluded are damages caused by improper use, overloading or failure to observe the operating instructions.


Art. No. 5707 061 2

P. Qty.: 1

Nominal voltage	230 V/AC
Min./max. frequency	50/60 Hz
Protection class	Protection class II/protective insulation
Power input	1700 W
Max. idle speed	11000 rpm
Max. cutting disc diameter.	125 mm
Thread type x spindle-thread diameter	M14
Weight of machine	2.6 kg
Cable length	4 m
Functions	Speed electronics, Speed adjustment wheel, Constant electronics, Recoil protection, Restarting protection, Soft start, Overloading protection, Quick clamping nut, Quickly adjustable cover, Anti-vibration system

Individually boxed. Machine can also be stored in case (see accessories).

Details/Application

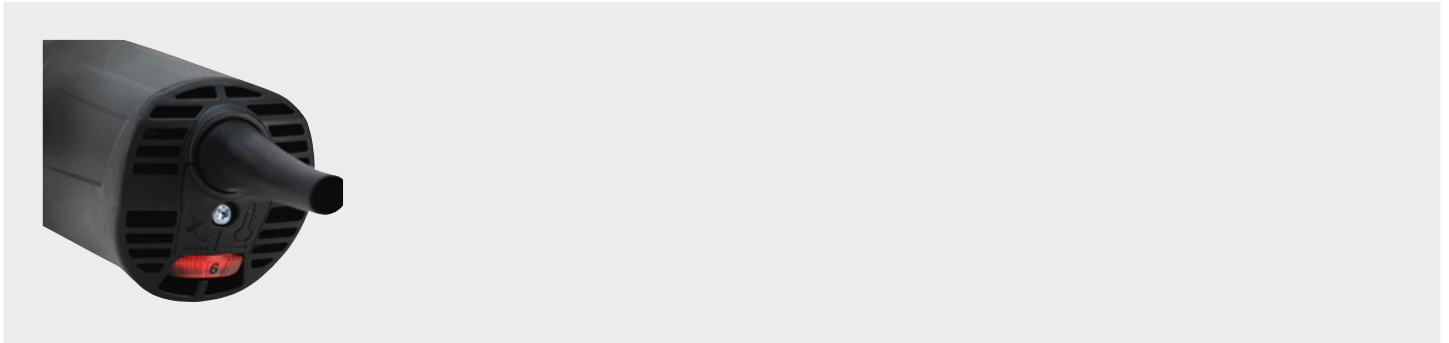

Contents for Art. No. 5707 061 2

Designation	Art. No.	Quantity
Q-Nut quick-clamping nut	5707 000 100	1
Protective cover	5807 003 014	1
Anti-vibration handle	5807 004 009	1

Related products

	Art. No.
Separating guard cover clip for angle grinder	5707 000 102
Dust protection filter for angle grinder	5707 000 106
Extractor hood WSA 125 for angle grinder	5707 000 107
Case insert	5807 003 995
System case 8.4.2	5581 011 000