

Cordless rechargeable LED hand-held lamp Ergopower Bend+

LED hand-held lamp with rotatable and flexible light head. With digital display for battery status and light intensity. With USB-C charging connection and wireless function.

Light levels:

- Main light: 70–700 lumens, stepless dimmable
- Spot light: 70 lumens

Switching sequence:

Spotlight/main light/off

Main light with dimming function – press and hold the button

The light flashes briefly when the lowest or highest light level is reached

Functional light head:

- It can be bent 180° and rotated 270°
- With a width of 9 mm, ideal for narrow spaces

Strong magnet on the underside of the light

Retractable hook

Automatic switch off

The switched on main light switches off automatically as soon as the light head with the light emitted is fully retracted into the light body.

The light can either be charged via the USB-C cable or the wireless charging pad (for the European market: Ergopower Pad I, art. no. 0827940991 or Pad II, art. no. 0827940992; For markets other than the European market: Ergopower Pad, art. no. 0827940091)

USB power supply and USB-C cable included in scope of delivery


Charging pad not included in scope of delivery



Details/Application



Details/Application

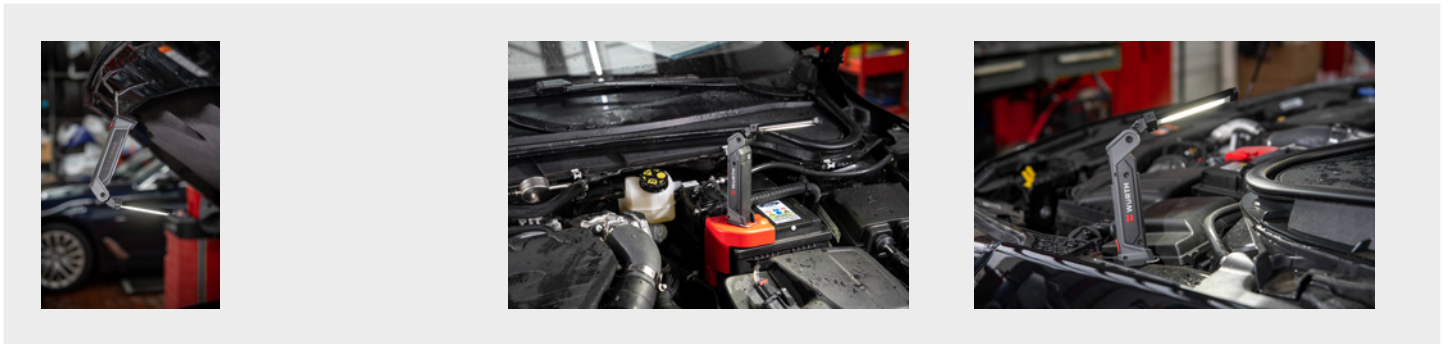

Notice

Lithium-ion battery, 3.7 V, 2600 mAh, 9.62 Wh