

## Storage box

For storing small parts, consumables and bulk materials in a way that makes them easy to locate. Ideal for workshops, trade businesses and industry.

- Resistant to common greases and oils
- Temperature-resistant from -20°C to +90°C
- Impact-resistant and break-proof

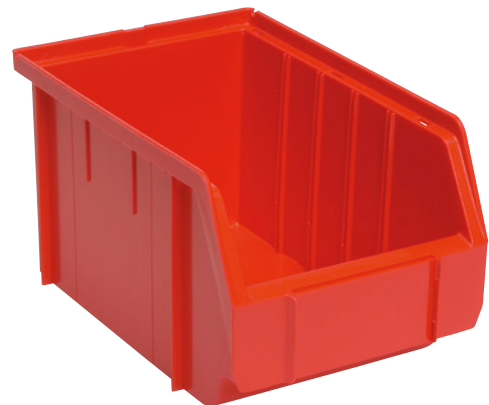


Illustration only

Material	PP - Polypropylene
----------	--------------------

Art. no.	0962 211 012	0962 211 013	0962 211 015	0962 211 011	0962 211 014	0962 211 022
P. Qty.	1	1	1	1	1	1
Size	1	1	1	1	1	2
Colour	Blue	Green	Grey	Red	Yellow	Blue
Length (L1)	489 mm	489 mm	489 mm	489 mm	489 mm	335 mm
Width (B2)	304 mm	304 mm	304 mm	304 mm	304 mm	209 mm
Height (H2)	185 mm	185 mm	185 mm	185 mm	185 mm	152 mm
Internal width (B1)	280 mm	280 mm	280 mm	280 mm	280 mm	191 mm
Height (from floor to stacking rim)	172 mm	172 mm	172 mm	172 mm	172 mm	139 mm
Length (internal base) (L3)	425 mm	425 mm	425 mm	425 mm	425 mm	293 mm


Art. no.	0962 211 023	0962 211 025	0962 211 021	0962 211 024	0962 211 032	0962 211 033
P. Qty.	1	1	1	1	1	1
Size	2	2	2	2	3	3
Colour	Green	Grey	Red	Yellow	Blue	Green
Length (L1)	335 mm	335 mm	335 mm	335 mm	230 mm	230 mm
Width (B2)	209 mm	209 mm	209 mm	209 mm	150 mm	150 mm
Height (H2)	152 mm	152 mm	152 mm	152 mm	130 mm	130 mm
Internal width (B1)	191 mm	191 mm	191 mm	191 mm	130 mm	130 mm
Height (from floor to stacking rim)	139 mm	139 mm	139 mm	139 mm	118 mm	118 mm
Length (internal base) (L3)	293 mm	293 mm	293 mm	293 mm	192 mm	192 mm

Art. no.	0962 211 035	0962 211 031	0962 211 034	0962 211 042	0962 211 043	0962 211 045
P. Qty.	1	1	1	1	1	1
Size	3	3	3	4	4	4
Colour	Grey	Red	Yellow	Blue	Green	Grey
Length (L1)	230 mm	230 mm	230 mm	161 mm	161 mm	161 mm
Width (B2)	150 mm	150 mm	150 mm	105 mm	105 mm	105 mm
Height (H2)	130 mm	130 mm	130 mm	75 mm	75 mm	75 mm
Internal width (B1)	130 mm	130 mm	130 mm	89 mm	89 mm	89 mm
Height (from floor to stacking rim)	118 mm	118 mm	118 mm	63 mm	63 mm	63 mm
Length (internal base) (L3)	192 mm	192 mm	192 mm	137 mm	137 mm	137 mm

Art. no.	0962 211 041	0962 211 044	0962 211 052	0962 211 053	0962 211 055	0962 211 051
P. Qty.	1	1	1	1	1	1
Size	4	4	5	5	5	5
Colour	Red	Yellow	Blue	Green	Grey	Red
Length (L1)	161 mm	161 mm	90 mm	90 mm	90 mm	90 mm
Width (B2)	105 mm	105 mm	102 mm	102 mm	102 mm	102 mm
Height (H2)	75 mm	75 mm	50 mm	50 mm	50 mm	50 mm
Internal width (B1)	89 mm	89 mm	88 mm	88 mm	88 mm	88 mm
Height (from floor to stacking rim)	63 mm	63 mm	44 mm	44 mm	44 mm	44 mm
Length (internal base) (L3)	137 mm	137 mm	68 mm	68 mm	68 mm	68 mm

Art. no.	0962 211 054
P. Qty.	1
Size	5
Colour	Yellow
Length (L1)	90 mm
Width (B2)	102 mm
Height (H2)	50 mm
Internal width (B1)	88 mm
Height (from floor to stacking rim)	44 mm
Length (internal base) (L3)	68 mm

## Technical Information

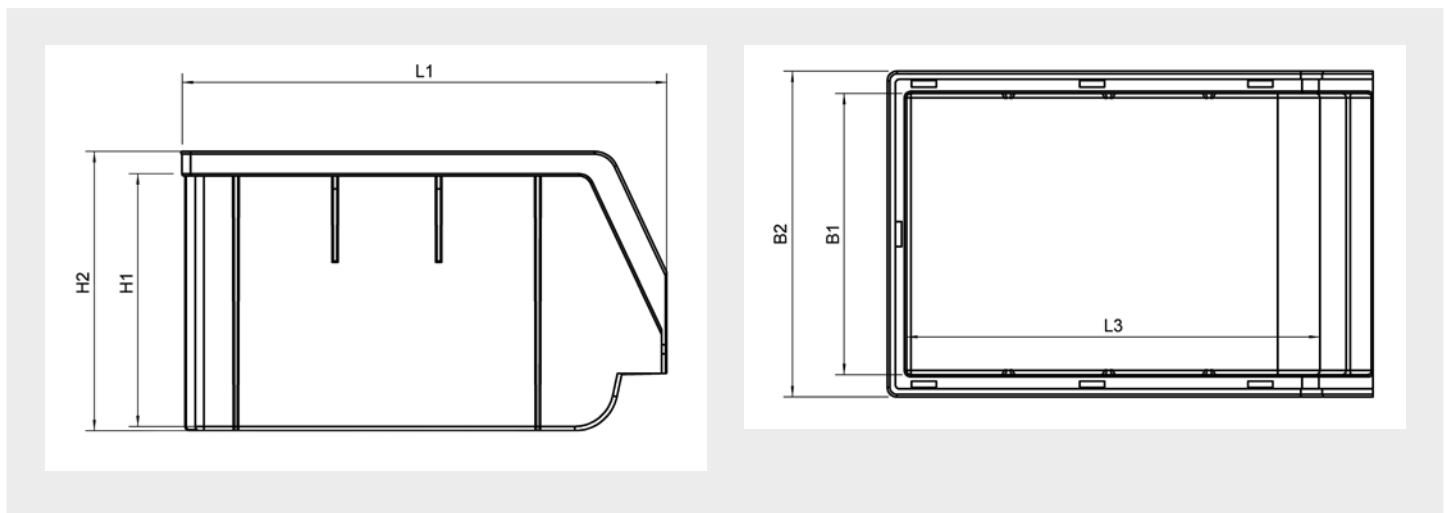

## Details/Application



Related products for	Designation	Art. no.
0962 211 011	Divider Long	0962 210 111
	Divider Short	0962 210 112
	Front flap	0962 210 113
	Identification label	0962 210 202
0962 211 012	Divider Long	0962 210 111
	Divider Short	0962 210 112
	Front flap	0962 210 113
	Identification label	0962 210 202
0962 211 013	Divider Long	0962 210 111
	Divider Short	0962 210 112
	Front flap	0962 210 113
	Identification label	0962 210 202
0962 211 014	Divider Long	0962 210 111
	Divider Short	0962 210 112
	Front flap	0962 210 113
	Identification label	0962 210 202
0962 211 015	Divider Long	0962 210 111
	Divider Short	0962 210 112
	Front flap	0962 210 113
	Identification label	0962 210 202
0962 211 021	Front flap	0962 210 113
	Divider Long	0962 210 121
	Divider Short	0962 210 122
	Lid	0962 210 152
	Identification label	0962 210 202

<b>Related products for</b>	<b>Designation</b>	<b>Art. no.</b>
0962 211 022	Front flap	<b>0962 210 113</b>
	Divider Long	<b>0962 210 121</b>
	Divider Short	<b>0962 210 122</b>
	Lid	<b>0962 210 152</b>
	Identification label	<b>0962 210 202</b>
0962 211 023	Front flap	<b>0962 210 113</b>
	Divider Long	<b>0962 210 121</b>
	Divider Short	<b>0962 210 122</b>
	Lid	<b>0962 210 152</b>
	Identification label	<b>0962 210 202</b>
0962 211 024	Front flap	<b>0962 210 113</b>
	Divider Long	<b>0962 210 121</b>
	Divider Short	<b>0962 210 122</b>
	Lid	<b>0962 210 152</b>
	Identification label	<b>0962 210 202</b>
0962 211 025	Front flap	<b>0962 210 113</b>
	Divider Long	<b>0962 210 121</b>
	Divider Short	<b>0962 210 122</b>
	Lid	<b>0962 210 152</b>
	Identification label	<b>0962 210 202</b>
0962 211 031	Divider	<b>0962 210 132</b>
	Front flap	<b>0962 210 133</b>
	Lid	<b>0962 210 153</b>
	Identification label	<b>0962 210 202</b>
0962 211 032	Divider	<b>0962 210 132</b>
	Front flap	<b>0962 210 133</b>
	Lid	<b>0962 210 153</b>
	Identification label	<b>0962 210 202</b>
0962 211 033	Divider	<b>0962 210 132</b>
	Front flap	<b>0962 210 133</b>
	Lid	<b>0962 210 153</b>
	Identification label	<b>0962 210 202</b>
0962 211 034	Divider	<b>0962 210 132</b>
	Front flap	<b>0962 210 133</b>
	Lid	<b>0962 210 153</b>
	Identification label	<b>0962 210 202</b>
0962 211 035	Divider	<b>0962 210 132</b>
	Front flap	<b>0962 210 133</b>
	Lid	<b>0962 210 153</b>
	Identification label	<b>0962 210 202</b>
0962 211 041	Divider	<b>0962 210 142</b>
	Lid	<b>0962 210 154</b>
	Identification label	<b>0962 210 203</b>
0962 211 042	Divider	<b>0962 210 142</b>
	Lid	<b>0962 210 154</b>
	Identification label	<b>0962 210 203</b>
0962 211 043	Divider	<b>0962 210 142</b>
	Lid	<b>0962 210 154</b>
	Identification label	<b>0962 210 203</b>
0962 211 044	Divider	<b>0962 210 142</b>
	Lid	<b>0962 210 154</b>
	Identification label	<b>0962 210 203</b>

<b>Related products for</b>	<b>Designation</b>	<b>Art. no.</b>
0962 211 045	Divider	<b>0962 210 142</b>
	Lid	<b>0962 210 154</b>
	Identification label	<b>0962 210 203</b>
0962 211 051	Identification label	<b>0962 210 203</b>
0962 211 052	Identification label	<b>0962 210 203</b>
0962 211 053	Identification label	<b>0962 210 203</b>
0962 211 054	Identification label	<b>0962 210 203</b>
0962 211 055	Identification label	<b>0962 210 203</b>