


## 1/4-inch socket wrench insert, TX head

### For TX head screws

- Surface: chrome-plated
- Drive: 1/4" square socket, ball catch groove
- Tip: For TX head screws



Drive	1/4 inch
Tip type	For outer TX

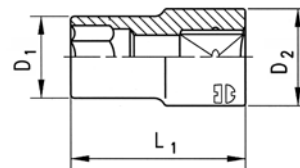

Tip size	Length (L1)	Socket wrench external diameter (D1)	Socket wrench external diameter 2 (D2)	Socket wrench depth (t)	Surface	Art. no.	P. Qty.
E4	22 mm	5.4 mm	12 mm		Chrome plated	<b>0715 112 04</b>	1/10
E4	25 mm	6.2 mm	11.9 mm	3.56 mm	Zinc phosphated	<b>0715 112 104</b>	10
E5	22 mm	6.7 mm	12 mm		Chrome plated	<b>0715 112 05</b>	1/10
E5	25 mm	6.9 mm	11.9 mm	4.19 mm	Zinc phosphated	<b>0715 112 105</b>	10
E6	22 mm	7.7 mm	12 mm		Chrome plated	<b>0715 112 06</b>	1/10
E6	25 mm	7.9 mm	11.9 mm	4.32 mm	Zinc phosphated	<b>0715 112 106</b>	10
E7	22 mm	8.3 mm	12 mm		Chrome plated	<b>0715 112 07</b>	1/10
E7	25 mm	8.8 mm	11.9 mm	5.59 mm	Zinc phosphated	<b>0715 112 107</b>	10
E8	22 mm	9.6 mm	12 mm		Chrome plated	<b>0715 112 08</b>	1/10
E8	25 mm	9.9 mm	11.9 mm	5.97 mm	Zinc phosphated	<b>0715 112 108</b>	10
E10	22 mm	11.3 mm	12 mm		Chrome plated	<b>0715 112 10</b>	1/10
E11	22 mm	12 mm	12 mm		Chrome plated	<b>0715 112 11</b>	1/10