

## Combination wrench assortment, short type

### Metric DIN 3113A/ISO 3318/7738

- **Drive:** Ring end POWERDRIV®, bi-hexagonal
- **Material:** Chromium-vanadium steel
- Surface: Chrome-plated, heads and ring polished
- Geometry: Ring end angled 15°, jaw angle 15°

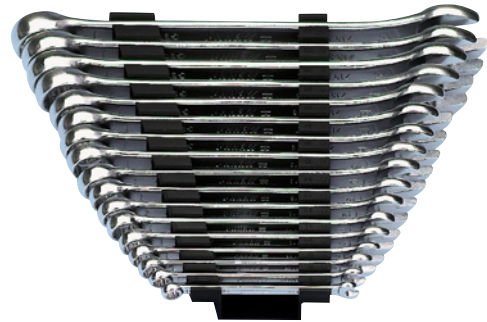


Illustration only



**POWERDRIV**

Number of pieces in assortment/set	Width across flats	Included in delivery	Art. no.	P. Qty.
11 PCS	8 mm, 9 mm, 10 mm, 11 mm, 12 mm, 13 mm, 14 mm, 15 mm, 17 mm, 19 mm, 22 mm		<b>0713 301 40</b>	1
17 PCS	6 mm, 7 mm, 8 mm, 9 mm, 10 mm, 11 mm, 12 mm, 13 mm, 14 mm, 15 mm, 16 mm, 17 mm, 18 mm, 19 mm, 20 mm, 21 mm, 22 mm		<b>0713 301 41</b>	1
28 PCS	5.5 mm, 6 mm, 7 mm, 8 mm, 9 mm, 10 mm, 11 mm, 12 mm, 13 mm, 14 mm, 15 mm, 16 mm, 17 mm, 18 mm, 19 mm, 20 mm, 21 mm, 22 mm, 23 mm, 24 mm, 25 mm, 26 mm, 27 mm, 28 mm, 29 mm, 30 mm, 32 mm, 34 mm	Supplied in two tool rolls	<b>0713 301 42</b>	1

#### Contents for art. no. 0713 301 40

Designation	Art. no.	Quantity
Combination wrench, short type 8 mm	<b>0713 301 08</b>	1
Combination wrench, short type 9 mm	<b>0713 301 09</b>	1
Combination wrench, short type 10 mm; Length 140 mm	<b>0713 301 10</b>	1
Combination wrench, short type 11 mm	<b>0713 301 11</b>	1
Combination wrench, short type 12 mm	<b>0713 301 12</b>	1
Combination wrench, short type 13 mm; Length 170 mm	<b>0713 301 13</b>	1
Combination wrench, short type 14 mm	<b>0713 301 14</b>	1
Combination wrench, short type 15 mm	<b>0713 301 15</b>	1
Combination wrench, short type 17 mm; Length 205 mm	<b>0713 301 17</b>	1
Combination wrench, short type 19 mm; Length 230 mm	<b>0713 301 19</b>	1
Combination wrench, short type 22 mm; Length 260 mm	<b>0713 301 22</b>	1
Plastic holder For combination wrench assortment	<b>0713 301 401</b>	1

#### Contents for art. no. 0713 301 41

Designation	Art. no.	Quantity
Combination wrench, short type 6 mm	<b>0713 301 06</b>	1
Combination wrench, short type 7 mm	<b>0713 301 07</b>	1

**Contents for art. no. 0713 301 41**

<b>Designation</b>	<b>Art. no.</b>	<b>Quantity</b>
Combination wrench, short type 8 mm	<b>0713 301 08</b>	1
Combination wrench, short type 9 mm	<b>0713 301 09</b>	1
Combination wrench, short type 10 mm; Length 140 mm	<b>0713 301 10</b>	1
Combination wrench, short type 11 mm	<b>0713 301 11</b>	1
Combination wrench, short type 12 mm	<b>0713 301 12</b>	1
Combination wrench, short type 13 mm; Length 170 mm	<b>0713 301 13</b>	1
Combination wrench, short type 14 mm	<b>0713 301 14</b>	1
Combination wrench, short type 15 mm	<b>0713 301 15</b>	1
Combination wrench, short type 16 mm	<b>0713 301 16</b>	1
Combination wrench, short type 17 mm; Length 205 mm	<b>0713 301 17</b>	1
Combination wrench, short type 18 mm	<b>0713 301 18</b>	1
Combination wrench, short type 19 mm; Length 230 mm	<b>0713 301 19</b>	1
Combination wrench, short type 20 mm	<b>0713 301 20</b>	1
Combination wrench, short type 21 mm	<b>0713 301 21</b>	1
Combination wrench, short type 22 mm; Length 260 mm	<b>0713 301 22</b>	1
Plastic holder For combination wrench assortment	<b>0713 301 411</b>	1

**Contents for art. no. 0713 301 42**

<b>Designation</b>	<b>Art. no.</b>	<b>Quantity</b>
Combination wrench, short type 5.5 mm	<b>0713 301 055</b>	1
Combination wrench, short type 6 mm	<b>0713 301 06</b>	1
Combination wrench, short type 7 mm	<b>0713 301 07</b>	1
Combination wrench, short type 8 mm	<b>0713 301 08</b>	1
Combination wrench, short type 9 mm	<b>0713 301 09</b>	1
Combination wrench, short type 10 mm; Length 140 mm	<b>0713 301 10</b>	1
Combination wrench, short type 11 mm	<b>0713 301 11</b>	1
Combination wrench, short type 12 mm	<b>0713 301 12</b>	1
Combination wrench, short type 13 mm; Length 170 mm	<b>0713 301 13</b>	1
Combination wrench, short type 14 mm	<b>0713 301 14</b>	1
Combination wrench, short type 15 mm	<b>0713 301 15</b>	1
Combination wrench, short type 16 mm	<b>0713 301 16</b>	1
Combination wrench, short type 17 mm; Length 205 mm	<b>0713 301 17</b>	1
Combination wrench, short type 18 mm	<b>0713 301 18</b>	1
Combination wrench, short type 19 mm; Length 230 mm	<b>0713 301 19</b>	1
Combination wrench, short type 20 mm	<b>0713 301 20</b>	1
Combination wrench, short type 21 mm	<b>0713 301 21</b>	1
Combination wrench, short type 22 mm; Length 260 mm	<b>0713 301 22</b>	1
Combination wrench, short type 23 mm	<b>0713 301 23</b>	1
Combination wrench, short type 24 mm; Length 280 mm	<b>0713 301 24</b>	1
Combination wrench, short type 25 mm	<b>0713 301 25</b>	1
Combination wrench, short type 26 mm	<b>0713 301 26</b>	1
Combination wrench, short type 27 mm; Length 310 mm	<b>0713 301 27</b>	1
Combination wrench, short type 28 mm	<b>0713 301 28</b>	1
Combination wrench, short type 29 mm	<b>0713 301 29</b>	1
Combination wrench, short type 30 mm; Length 340 mm	<b>0713 301 30</b>	1
Combination wrench, short type 32 mm; Length 350 mm	<b>0713 301 32</b>	1
Combination wrench, short type 34 mm	<b>0713 301 34</b>	1